


No. 140 1 3/4" Pitch — Multiple Strand



Pitch	Inner width	Roller- ø
inch	inch	inch
1 3/4"	1"	1.000"

† Dimensions shown allow for standard keyway with set screw at 90°

Sprockets supplied without keyway and setscrews unless specifically requested.

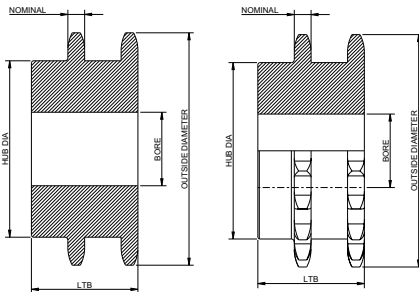

Basic Sprocket Dimensions				140-2 Double Strand				
No. Teeth	Outside Diameter	Pitch Diameter	Plain Bore	Catalog Number	Hub Dia.	LTB	†Max. Bore	Wt. Lbs.
13	8.150	7.313	1 5/8	D140B13	5	3 3/4	3 5/16	29.00
14	8.720	7.865	1 5/8	D140B14	5 1/2	3 3/4	3 3/4	34.80
15	9.280	8.418	1 5/8	D140B15	6 1/2	3 3/4	4 1/2	42.50
16	9.850	8.971	1 5/8	D140B16	7	4	5 1/4	48.10
17	10.410	9.524	1 5/8	D140B17	7	4	5 1/4	57.50
18	10.980	10.078	1 3/4	D140B18	7	4	5 1/4	65.60
19	11.540	10.633	1 3/4	D140B19	7	4	5 1/4	72.00
20	12.100	11.186	1 3/4	D140B20	7	4	5 1/4	76.00
21	12.660	11.743	1 3/4	D140B21	7	4	5 1/4	82.00
22	13.220	12.297	1 3/4	D140B22	7	4	5 1/4	94.00
23	13.780	12.852	1 3/4	D140B23	7	4	5 1/4	100.00
24	14.340	13.407	1 3/4	D140B24	7	4	5 1/4	104.00
25	14.900	13.963	1 3/4	D140B25	7	4	5 1/4	120.00
26	15.460	14.518	1 3/4	D140B26	7	4	5 1/4	128.00

Some sizes are Made-To-Order, consult iwis for availability.