

No. 180 2 1/4" Pitch — Plain Bore

Pitch	Inner width	Roller- ø
inch	inch	inch
2 1/4"	1 13/32"	1.406"

† Dimensions shown allow for standard keyway with set screw at 90°
★ Hub diameter may vary to suit bore sizes


Sprockets supplied without keyway and setscrews
unless specifically requested.



Sprocket Diameters 2 1/4" Pitch			Type A			Type B					
No. Teeth	Outside Diameter	Pitch Diameter	Catalog Number	Plain Bore	Wt. Lbs.	Catalog Number	Plain Bore	†Max. Bore	★ Hub Dia.	LTB	Wt. Lbs.
11	9.010	7.986	180A11	1 1/2	14.00	180B11	1 1/2	3 5/8	5 1/2	3	29.00
12	9.750	8.693	180A12	1 1/2	16.00	180B12	1 1/2	4	6	3	32.00
13	10.480	9.402	180A13	1 1/2	20.00	180B13	1 1/2	4 5/8	6 3/4	3 5/8	40.00
14	11.210	10.112	180A14	1 1/2	24.00	180B14	1 1/2	5 1/4	7	3 5/8	44.00
15	11.930	10.822	180A15	1 1/2	28.00	180B15	1 1/2	5 1/4	7	3 5/8	48.00
16	12.660	11.533	180A16	1 1/2	32.00	180B16	1 1/2	5 1/4	7	3 5/8	52.00
17	13.390	12.245	180A17	1 1/2	37.00	180B17	1 1/2	5 1/4	7	3 5/8	58.00
18	14.110	12.957	180A18	1 1/2	43.00	180B18	1 1/2	5 1/4	7	3 5/8	63.00
19	14.830	13.670	180A19	1 1/2	47.00	180B19	1 1/2	5 5/8	7 1/2	3 5/8	74.00
20	15.560	14.383	180A20	1 1/2	53.00	180B20	1 1/2	5 5/8	7 1/2	3 5/8	81.00
21	16.280	15.096	180A21	1 1/2	57.00	180B21	1 1/2	5 5/8	7 1/2	3 5/8	83.00
22	17.000	15.810	180A22	1 1/2	62.00	180B22	1 1/2	5 5/8	7 1/2	3 5/8	92.00
23	17.720	16.524	180A23	1 1/2	69.00	180B23	1 1/2	5 5/8	7 1/2	3 5/8	99.00
24	18.440	17.238	180A24	1 1/2	77.00	180B24	1 1/2	5 5/8	7 1/2	3 5/8	105.00
25	19.160	17.952	180A25	1 1/2	84.00	180B25	1 1/2	5 5/8	7 1/2	3 5/8	113.00
28	21.320	20.096	180A28	1 1/2	104.00	180B28	1 1/2	5 1/2	8	3 1/2	135.00
30	22.760	21.525	180A30	1 1/2	120.00						
35	26.350	25.101	180A35	1 1/2	172.00						
40	29.940	28.677	180A40	1 1/2	229.00						
45	33.530	32.255	180A45	1 1/2	284.00						
54	39.980	38.696	180A54	1 1/2	420.00						
60	44.280	42.992	180A60	1 1/2	505.00						

Some sizes are Made-To-Order, consult iwis for availability.

TYPE A

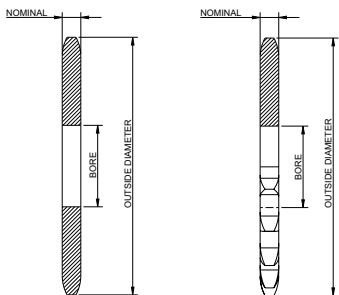

TYPE B

