

No. 60 $\frac{3}{4}$ " Pitch — Multiple Strand



Basic Sprocket Dimensions				60-2 Double Strand					60-3 Triple Strand				
No. Teeth	Outside Diameter	Pitch Diameter	Plain Bore	Catalog Number	Hub Dia.	LTB	†Max. Bore	Wt. Lbs.	Catalog Number	Hub Dia.	LTB	†Max. Bore	Wt. Lbs.
11	3.010	2.663	1	D60B11	1 $\frac{13}{16}$	2 $\frac{1}{8}$	1 $\frac{1}{4}$	1.62	T60B11	1 $\frac{13}{16}$	3	1 $\frac{1}{4}$	2.50
12	3.250	2.898	1	D60B12	2 $\frac{1}{8}$	2 $\frac{1}{8}$	1 $\frac{7}{16}$	2.20	T60B12	2 $\frac{1}{8}$	3	1 $\frac{7}{16}$	3.30
13	3.490	3.134	1	D60B13	2 $\frac{1}{4}$	2 $\frac{1}{8}$	1 $\frac{1}{2}$	2.60	T60B13	2 $\frac{1}{4}$	3	1 $\frac{1}{2}$	3.90
14	3.740	3.371	1	D60B14	2 $\frac{1}{2}$	2 $\frac{1}{8}$	1 $\frac{3}{4}$	3.24	T60B14	2 $\frac{1}{2}$	3	1 $\frac{3}{4}$	4.50
15	3.980	3.608	1	D60B15	2 $\frac{13}{16}$	2 $\frac{1}{8}$	1 $\frac{7}{8}$	3.96	T60B15	2 $\frac{13}{16}$	3	1 $\frac{7}{8}$	5.40
16	4.220	3.845	1	D60B16	3	2 $\frac{1}{8}$	2	4.62	T60B16	3	3	2	6.50
17	4.460	4.082	1	D60B17	3 $\frac{1}{4}$	2 $\frac{1}{8}$	2 $\frac{1}{4}$	5.40	T60B17	3 $\frac{1}{4}$	3	2 $\frac{1}{4}$	7.70
18	4.700	4.319	1	D60B18	3 $\frac{1}{2}$	2 $\frac{1}{8}$	2 $\frac{3}{8}$	6.24	T60B18	3 $\frac{1}{2}$	3	2 $\frac{3}{8}$	8.50
19	4.950	4.557	1	D60B19	3 $\frac{11}{16}$	2 $\frac{1}{8}$	2 $\frac{1}{2}$	7.00	T60B19	3 $\frac{11}{16}$	3	2 $\frac{1}{2}$	10.00
20	5.190	4.794	1	D60B20	3 $\frac{3}{4}$	2 $\frac{1}{8}$	2 $\frac{1}{2}$	7.72	T60B20	3 $\frac{3}{4}$	3	2 $\frac{1}{2}$	11.20
21	5.430	5.033	1	D60B21	4 $\frac{1}{8}$	2 $\frac{1}{8}$	2 $\frac{3}{4}$	8.82	T60B21	4 $\frac{1}{8}$	3	2 $\frac{3}{4}$	12.50
22	5.670	5.270	1	D60B22	4 $\frac{1}{4}$	2 $\frac{1}{8}$	2 $\frac{3}{4}$	9.68	T60B22	4 $\frac{1}{4}$	3	2 $\frac{3}{4}$	13.20
23	5.910	5.508	1	D60B23	4 $\frac{1}{4}$	2 $\frac{1}{8}$	2 $\frac{3}{4}$	10.30	T60B23	4 $\frac{1}{4}$	3	2 $\frac{3}{4}$	14.60
24	6.150	5.746	1	D60B24	4 $\frac{1}{4}$	2 $\frac{1}{8}$	2 $\frac{3}{4}$	11.14	T60B24	4 $\frac{1}{4}$	3	2 $\frac{3}{4}$	15.80
25	6.390	5.984	1	D60B25	4 $\frac{1}{4}$	2 $\frac{1}{8}$	2 $\frac{3}{4}$	11.96	T60B25	4 $\frac{1}{4}$	3	2 $\frac{3}{4}$	17.00
26	6.630	6.222	1	D60B26	4 $\frac{1}{4}$	2 $\frac{1}{8}$	2 $\frac{3}{4}$	12.70	T60B26	4 $\frac{1}{4}$	3	2 $\frac{3}{4}$	18.60
30	7.590	7.175	1	D60B30	4 $\frac{1}{4}$	2 $\frac{1}{8}$	2 $\frac{3}{4}$	16.36	T60B30	4 $\frac{1}{4}$	3	2 $\frac{3}{4}$	23.00
32	8.070	7.652	1 $\frac{1}{4}$	D60B32	4 $\frac{1}{2}$	2 $\frac{3}{8}$	3	19.52					
35	8.780	8.367	1 $\frac{1}{4}$	D60B35	4 $\frac{1}{2}$	2 $\frac{3}{8}$	3	22.80	T60B35	4 $\frac{1}{2}$	3 $\frac{1}{4}$	3	34.50
36	9.020	8.606	1 $\frac{1}{4}$	D60B36	4 $\frac{1}{2}$	2 $\frac{3}{8}$	3	23.82	T60B36	4 $\frac{1}{2}$	3 $\frac{1}{4}$	3	37.00
40	9.980	9.560	1 $\frac{1}{4}$	D60B40	4 $\frac{3}{4}$	2 $\frac{3}{4}$	3 $\frac{1}{4}$	30.84					
45	11.180	10.752	1 $\frac{1}{4}$	D60B45	4 $\frac{3}{4}$	2 $\frac{3}{4}$	3 $\frac{1}{4}$	37.08					
60	14.760	14.330	1 $\frac{1}{4}$	D60B60	4 $\frac{3}{4}$	2 $\frac{3}{4}$	3 $\frac{1}{4}$	63.10					


Some sizes are Made-To-Order, consult iwis for availability.

Pitch	Inner width	Roller- Ø
inch	inch	inch
$\frac{3}{4}$ "	$\frac{1}{2}$ "	.469"

† Dimensions shown allow for standard keyway with set screw at 90°

Sprockets supplied without keyway and setscrews unless specifically requested.

TYPE B – Double Strand

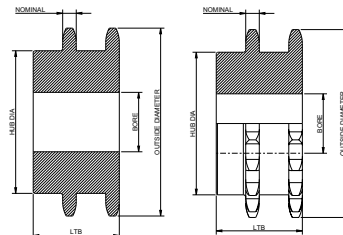

TYPE B – Triple Strand

